


# Parallel kit EAMM-U-50-D32-38AA-78

Part number: 8058924

FESTO

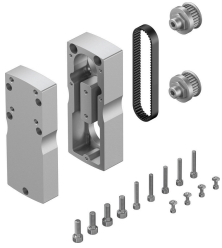

## Data sheet

Feature	Value
Size	50
Mounting position	optional
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	12.1 kgmm <sup>2</sup>
Frictional torque independent of load	0.01 Nm
Transmittable torque	1 Nm
Product weight	600 g
Interface code, actuator	D32
Interface code, motor in	38AA
Note on materials	RoHS-compliant