


# coupling socket NPHS-D6-M-G38

Part number: 8059276

FESTO

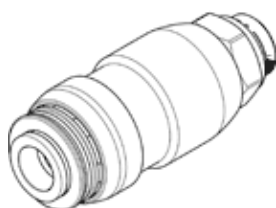

## Data sheet

Feature	Value
Nominal size	10 mm
Operating pressure complete temperature range	-0.95 ... 20 bar
Standard nominal flow rate	2,050 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-20 ... 80 °C
Nominal tightening torque	15 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	179 g
Pneumatic connection, port 1	Male thread G3/8
Materials note	Conforms to RoHS