


# Axial kit EAMM-A-L38-58AA

Part number: 8063456

FESTO

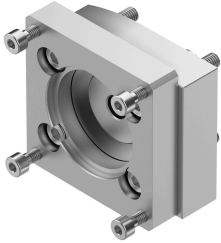

## Data sheet

| Feature                  | Value          |
|--------------------------|----------------|
| Mounting position        | optional       |
| LABS (PWIS) conformity   | VDMA24364-B2-L |
| Storage temperature      | -25 °C...60 °C |
| Relative air humidity    | 0 - 95%        |
| Degree of protection     | IP40           |
| Ambient temperature      | -10 °C...60 °C |
| Transmittable torque     | 9 Nm           |
| Product weight           | 267 g          |
| Interface code, actuator | L38            |
| Interface code, motor in | 58AA           |
| Note on materials        | RoHS-compliant |