


# axial kit EAMM-A-N80-84AA

Part number: 8063606

FESTO

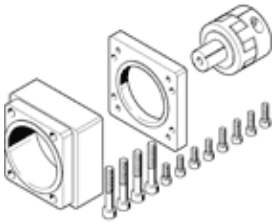

## Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	47 Nm
Product weight	1,477 g
Interface code, actuator	N80
Interface code, motor in	84AA
Materials note	Conforms to RoHS