


manifold rail

VABM-P6-15M-G18-M5-4

Part number: 8083543

FESTO

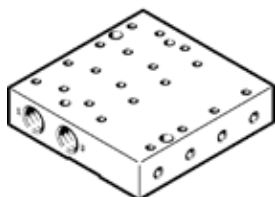

Data sheet

| Feature | Value |
|---|----------------------------------|
| Grid dimension | 15 mm |
| Design structure | Connection direction on the side |
| Max. number of valve positions | 4 |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B2-L |
| Max. tightening torque, valve mounting | 0.6 Nm |
| Product weight | 140 g |
| Pneumatic connection, port 1 | G1/8 |
| Pneumatic connection, port 2 | M5 |
| Materials note | Conforms to RoHS |
| Material manifold | Wrought Aluminium alloy |