


# Axial kit EAMM-A-V25-40R

Part number: 8087062

FESTO

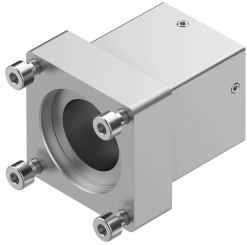

## Data sheet

Feature	Value
Nominal length	46 mm
Mounting position	optional
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	0.19 kgmm <sup>2</sup>
Transmittable torque	0.5 Nm
Product weight	107 g
Interface code, actuator	V25
Interface code, motor in	40R
Note on materials	RoHS-compliant