


axial kit EAMM-A-T42-60AB

Part number: 8094949

FESTO

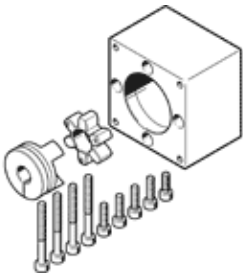

Data sheet

Feature	Value
Nominal length	43 mm
Assembly position	Any
Max. speed	8,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Mass moment of inertia	3.2 kgmm ²
Transferable torque	9.5 Nm
Product weight	314 g
Interface code, actuator	T42
Interface code, motor in	60AB
Materials note	Conforms to RoHS