


Axial kit EAMM-A-T46-70AA

Part number: 8096057

FESTO

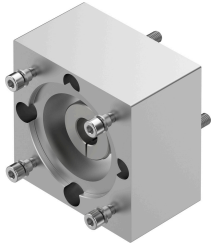

Data sheet

Feature	Value
Nominal length	47 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	3.2 kgmm ²
Transmittable torque	10 Nm
Product weight	601 g
Interface code, actuator	T46
Interface code, motor in	70AA
Note on materials	RoHS-compliant