


axial kit EAMM-A-V32-58AA

Part number: 8098982

FESTO

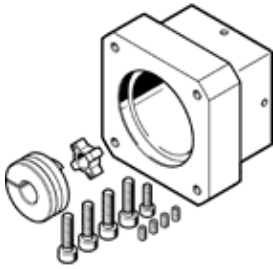

Data sheet

| Feature | Value |
|--------------------------|------------------------|
| Nominal length | 41 mm |
| Assembly position | Any |
| Max. speed | 10,000 1/min |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | -10 ... 60 °C |
| Mass moment of inertia | 1.03 kgmm ² |
| Transferable torque | 1.5 Nm |
| Product weight | 192 g |
| Interface code, actuator | V32 |
| Interface code, motor in | 58AA |
| Materials note | Conforms to RoHS |