


coupling
EAMC-56-58-22-25
Part number: 8099431

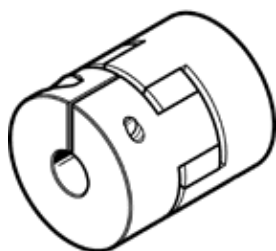

Data sheet

Feature	Value
Holder diameter 1	22 mm
Holder diameter 2	25 mm
Size	56
Nominal length	58 mm
Assembly position	Any
Max. speed	5,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	128 kgmm ²
Transferable torque	60 Nm
Product weight	272 g
Materials note	Conforms to RoHS