


Exhaust plate VABF-B14-M3-N14

Part number: 8099627

FESTO

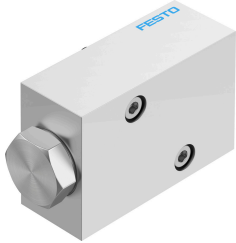

Data sheet

Feature	Value
Mounting position	optional
Operating pressure	1.5 bar...10 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C...80 °C
Media temperature	-20 °C...80 °C
Ambient temperature	-20 °C...80 °C
Product weight	280.5 g
Type of mounting	With through-hole
Pneumatic connection, port 1	1/4 NPT
Pneumatic connection, port 2	Flange 1/4 with NAMUR port pattern
Pneumatic connection, port 4	Flange 1/4 with NAMUR port pattern 1/4 NPT
Note on materials	RoHS-compliant
Material regulator housing	Wrought aluminium alloy