


Axial kit EAMM-A-P4-28B-38AA

Part number: 8107704

FESTO

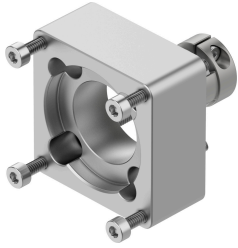

Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transmittable torque	0.7 Nm
Product weight	59 g
Interface code, actuator	P4-28B
Interface code, motor in	38AA
Note on materials	RoHS-compliant