


coupling

EAMD-42-48-19-16X25

Part number: 8121127

FESTO

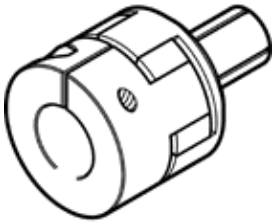

Data sheet

Feature	Value
Holder diameter 1	19 mm
Holder diameter 2	16 mm
Size	42
Nominal length	48 mm
Assembly position	Any
Max. speed	6,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	45 kgmm ²
Transferable torque	17 Nm
Product weight	212 g
Materials note	Conforms to RoHS