 



valve

VOFC-LT-M32C-MC-N14-FN

Part number: 8122933

FESTO

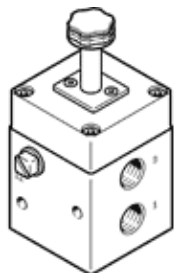

Data sheet

Feature	Value
Standard nominal flow rate	703 l/min
Operating pressure MPa	0.1 ... 0.8 MPa
Operating pressure	1 ... 8 bar
Protection class	IP65
Certificate issuing department	TÜV 968/V 1251.00/21
Safety function	Safe venting
Safety Integrity Level (SIL)	Product can be used in SRP/CS up to SIL 3 (high demand) bis SIL 3 Low Demand mode
Note on operating pressure	0 - 0.8 MPa with external pilot air
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Materials note	Conforms to RoHS