


# axial kit EAMM-A-D32-40RA

Part number: 8125610

FESTO

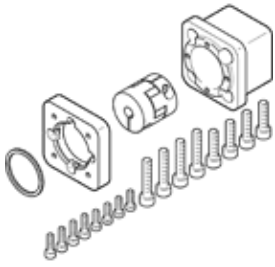

## Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	6.5 Nm
Product weight	309 g
Interface code, actuator	D32
Interface code, motor in	40RA
Materials note	Conforms to RoHS