


# coupling EAMC-19-20-5-9

Part number: 8126386

FESTO

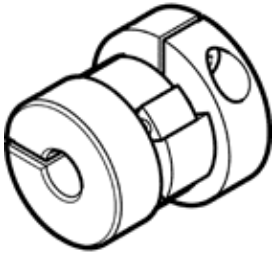

## Data sheet

Feature	Value
Holder diameter 1	5 mm
Holder diameter 2	9 mm
Size	19
Nominal length	20 mm
Assembly position	Any
Max. speed	10,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	0.38 kgmm <sup>2</sup>
Transferable torque	1.1 Nm
Product weight	9 g
Materials note	Conforms to RoHS