


# control plate DADG-FM-VDE1G18

Part number: 8131546

FESTO

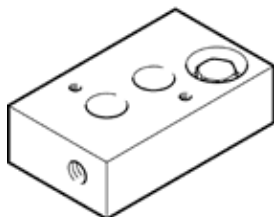

## Data sheet

Feature	Value
Based on the standard	VDI/VDE 3845 (NAMUR)
Assembly position	Any
Operating pressure MPa	0.2 ... 0.8 MPa
Operating pressure	2 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364 zone III
Ambient temperature	-20 ... 80 °C
Max. tightening torque	9 Nm
Product weight	227 g
Mounting type	Direct mounting on end cap via thread
Pneumatic connection	G1/8
Materials note	Conforms to RoHS
Material seals	NBR High alloy steel, non-corrosive
Material housing	Anodised aluminium
Material screws	Nickel-plated brass