


**coupling**  
**EAMC-56-58-22-24**  
Part number: 8134826

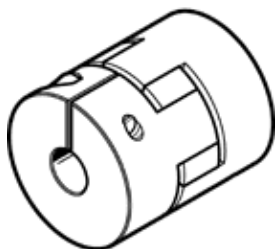

**Data sheet**

Feature	Value
Holder diameter 1	22 mm
Holder diameter 2	24 mm
Size	56
Nominal length	58 mm
Assembly position	Any
Max. speed	5,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	129 kgmm <sup>2</sup>
Transferable torque	60 Nm
Product weight	274 g
Materials note	Conforms to RoHS