


Gear unit EMGA-40-P-G12-EAS-40

Part number: 8141730

FESTO

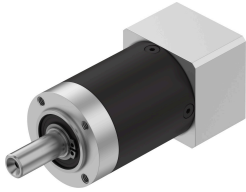

Data sheet

| Feature | Value |
|-------------------------------------|-------------------------|
| Gear unit flange size | 40 mm |
| Motor flange size | 40 mm |
| Torsional backlash | 0.31 deg |
| Type of gear unit | Planetary gear |
| Gear unit ratio | 12:1 |
| Max. drive speed | 18000 rpm |
| Operating temperature of gear unit | -25 °C...90 °C |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Degree of protection | IP54 |
| Continuous output torque | 20 Nm |
| Mass moment of inertia of gear unit | 0.025 kgcm ² |
| Max. output torque | 32 Nm |
| Max. efficiency | 96 % |
| Torsional rigidity | 1 Nm/arcmin |
| Product weight | 450 g |
| Gear unit interface, output shaft | 40G |
| Gear unit interface, drive shaft | 40P |
| Note on materials | RoHS-compliant |