


# Axial kit EAMM-A-D80-150A

Part number: 8157273

FESTO

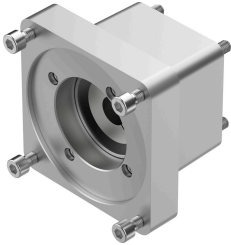

## Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transmittable torque	60 Nm
Product weight	3058 g
Interface code, actuator	D80B
Interface code, motor in	140A 150A
Note on materials	RoHS-compliant