


sub-base VMPA14-AP-4-EMG-D2-8-S

Part number: 8157742

FESTO

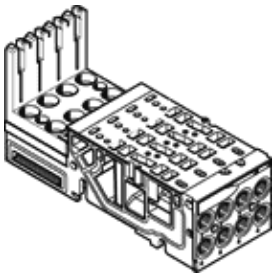

Data sheet

Feature	Value
Width	65.5 mm
Length	107.3 mm
Grid dimension	14 mm
Max. number of valve positions	4
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 60 °C
Ambient temperature	-5 ... 50 °C
Product weight	320 g
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 4	G1/8
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium die cast