


# Axial kit EAMM-A-X48-57A

Part number: 8165289

FESTO

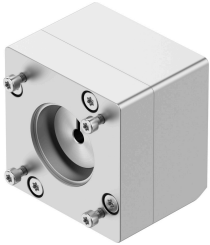

## Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transmittable torque	6.5 Nm
Product weight	614 g
Interface code, motor in	57A
Note on materials	RoHS-compliant