


Distributor block FR-12-PK-4-B

Part number: 8762

FESTO

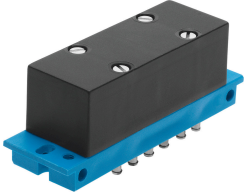

Data sheet

Feature	Value
Nominal size	3.4 mm
Mounting position	optional
Operating pressure complete temperature range	0 bar...8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Number of outputs	12
Number of supply lines	1
Pneumatic connection, port 1	Female thread G1/4
Pneumatic connection, port 2	For tubing outside diameter of 6 mm
Note on materials	RoHS-compliant
Material housing	Die-cast aluminium