

 

# pressure sequence valve

## VD-3-PK-3

Part number: 9270

FESTO

With sub-base 2n for tube ND 3 mm.

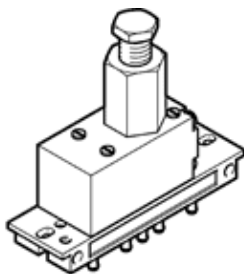

## Data sheet

Feature	Value
Standard nominal flow rate	100 l/min
Operating pressure MPa	0.18 ... 0.8 MPa
Operating pressure	1.8 ... 8 bar
Nominal size	2.5 mm
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Product weight	220 g
Mounting type	with through hole
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Pneumatic connection, port 3	PK-3
Materials note	Conforms to RoHS