


Round cylinder DGS-16- -P-A

Part number: 9324
Product to be discontinued

FESTO

With elastic cushioning rings in end positions
Type to be discontinued. Available until 2016. See Support Portal for alternative products.

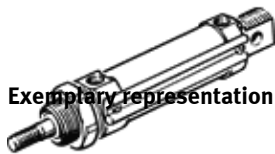

Exemplary representation



Data sheet

Feature	Value
Stroke	10 ... 400 mm
Piston diameter	16 mm
Cushioning	P: Flexible cushioning rings/plates at both ends
Position detection	For proximity sensor
Variants	Single-ended piston rod
Operating pressure	1 ... 10 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Ambient temperature	-20 ... 80 °C
Theoretical force at 6 bar, return stroke	91 N
Theoretical force at 6 bar, advance stroke	121 N
Pneumatic connection	G1/8