


Pressure indicator OH-10

Part number: 9791

FESTO

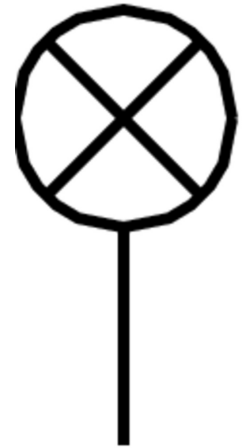

Data sheet

| Feature | Value |
|------------------------------------|--|
| Operating pressure | 0.14 MPa...0.8 MPa 1.4 bar...8 bar 20.3 psi...116 psi |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible (in which case lubricated operation will always be required) |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C...80 °C |
| Product weight | 4 g |
| Pneumatic connection | Barbed fitting PK-3 |
| Note on materials | RoHS-compliant |