


# Cartridge QSPLLK18-1/4-U

Part number: 132179

FESTO

With push-in connector, long L-form

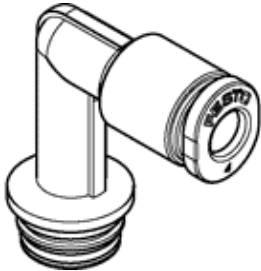

## Data sheet

Feature	Value
Size	Mini
Nominal size	3.6 mm
Assembly position	Any
Container size	10
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 10 bar
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-5 ... 60 °C
Product weight	4.2 g
Pneumatic connection, port 1	QSP...18
Pneumatic connection, port 2	for tubing, 1/4" outside diameter
color of release ring	Grey
Materials note	Conforms to RoHS
Material housing	PA-reinforced
Material release ring	POM
Material of tubing seal	NBR
Material of tube retaining claw	High alloy steel, non-corrosive