


Push-in bulkhead connector NPQP-H-Q10-E

Part number: 132551

FESTO

Type to be discontinued. Available until 2013.

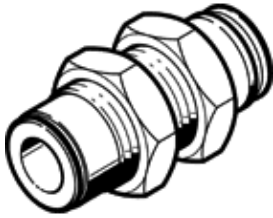

Data sheet

| Feature | Value |
|---|--|
| Size | Standard |
| Nominal size | 7.1 mm |
| Design structure | Push/pull principle |
| Temperature dependent working pressure | -0.95 ... 10 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 4 |
| Ambient temperature | -20 ... 60 °C |
| Product weight | 24.4 g |
| Pneumatic connection, port 1 | for tubing, 10mm outside diameter |
| Pneumatic connection, port 2 | for tubing, 10mm outside diameter |
| Materials note | Contains PWIS substances Conforms to RoHS |
| Materials information, housing | PP |
| Hose clamping segment material data | High alloy steel, non-corrosive |