

Manifold strip


VABM-C8-12E-G14-4-M1-L

Part number: 1361865

Classic - do not use for new projects

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

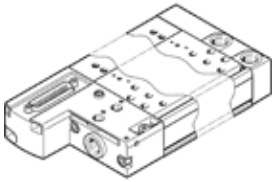

Data sheet

Feature	Value
Grid dimension	12 mm
Max. number of valve positions	4
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque, valve mounting	0.6 Nm
Max. tightening torque, wall mounting	5 Nm
Product weight	484 g
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 5	G1/4
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminum alloy