


# Socket connector MSSD-E

Part number: 14098

FESTO

For solenoid coils and valves, port pattern for JMEH, MEH and MOEH valves.

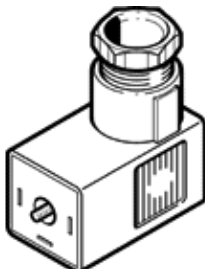

## Data sheet

Feature	Value
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	8 g
Electrical connection 1	Angled socket, square design, 3-pin, type C
Electrical connection 2	Screwed terminal
Operating voltage range DC	0 ... 300 V
Operating voltage range AC	0 ... 250 V
Acceptable current load at 40°C	6 A
Cable gland connection	Pg7
Cable diameter	6 ... 8 mm
Terminal cross-section	0.75 mm <sup>2</sup>
Protection class	IP65
Ambient temperature	-25 ... 90 °C
PWIS conformity	VDMA24364-B2-L
Degree of contamination	3
Material housing	PA-reinforced
Housing color	Black
Material seals	NBR