


# One-way flow control valve GRLA-1/8-NPT-B

Part number: 151539

FESTO

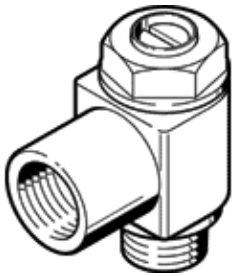

## Data sheet

Feature	Value
Valve function	One-way flow control function for exhaust air
Pneumatic connection, port 1	1/8 NPT
Pneumatic connection, port 2	1/8 NPT
Adjusting element	Slotted head screw
Mounting type	Threaded
Ambient temperature	-10 ... 60 °C
Operating pressure complete temperature range	0.3 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B2-L
Medium temperature	-10 ... 60 °C
Materials note	Conforms to RoHS