


# Intermediate plate MUH-ZP-D-3-L-24G

Part number: 151715  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2026. See Support Portal for alternative products.

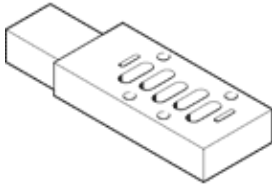

## Data sheet

Feature	Value
Nominal size	14.5 mm
Grid dimension	72 mm
Type of actuation	electrical
Assembly position	Any
Manual override	Pushing
Type of reset	mechanical spring
Type of piloting	direct
Flow direction	non reversible
Working pressure	-0.9 ... 10 bar
Pilot pressure	2 ... 10 bar
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	+/- 10 %
Authorization	c UL us - Recognized (OL)
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Storage temperature	-20 ... 40 °C
Medium temperature	-5 ... 50 °C
Protection class	IP65
Pilot medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Ambient temperature	-5 ... 50 °C
Product weight	500 g
Mounting type	with through hole
Materials note	Conforms to RoHS
Material seals	NBR