 



Non-return valve HB-1/2-QS-12

Part number: 153461

FESTO

Flow rate from the QS plug connector to the male thread.
This type is suitable for vacuum.

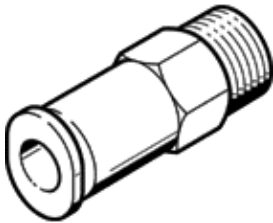

Data sheet

| Feature | Value |
|-------------------------------------|---|
| Valve function | Non-return function |
| Pneumatic connection, port 1 | QS-12 |
| Pneumatic connection, port 2 | R1/2 |
| Mounting type | Threaded |
| Standard nominal flow rate | 2,206 l/min |
| Working pressure | -1 ... 10 bar |
| Ambient temperature | 0 ... 60 °C |
| Material housing | Anodised aluminium |
| Housing color | silver |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Min. differential pressure, opening | 0.1 bar |
| Min. differential pressure, closing | 0.2 bar |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Product weight | 69 g |
| Materials note | Conforms to RoHS |