


# Ball valve

## QH-QS-4

Part number: 153483

FESTO

with QS push-in connector.  
This type is suitable for vacuum.

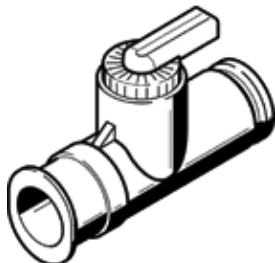

## Data sheet

Feature	Value
Valve function	2/2 bistable
Pneumatic connection, port 1	QS-4
Pneumatic connection, port 2	QS-4
Type of actuation	manual
Mounting type	Line installation
Standard nominal flow rate	148 l/min
Nominal size	2.5 mm
Operating pressure MPa	-0.1 ... 1 MPa
Working pressure	-1 ... 10 bar
Ambient temperature	0 ... 60 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Sealing principle	soft
Design structure	Ball valve
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Product weight	12 g
Materials note	Conforms to RoHS