

 

Pressure regulator

LR-1/8-QS-6

Part number: 153535
 Product to be discontinued

FESTO

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

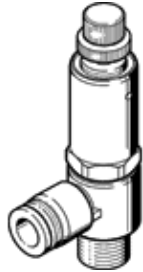

Data sheet

Feature	Value
Controller function	Output pressure constant with secondary exhaust
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	QS-6
Mounting type	Threaded
Standard nominal flow rate	63 l/min
Inlet pressure 1	0 ... 9 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Actuator lock	Knurled screw with lock nut
Assembly position	Any
Design structure	directly-controlled piston regulator with looped-through compressed air supply
Pressure regulation range	1 ... 8 bar
Product weight	36 g
Material of threaded plug	Brass Nickel plated
Material of threaded seal	PTFE