


# Linear actuator DGP-2 1/2"- -PPV-A-B

Part number: 160914


FESTO

For proximity sensing, rodless, with positive-locking connection between piston and actuator and adjustable end-position cushioning at both ends.

This product is only available if ordered from the Festo Corporation, USA.  
Type to be discontinued. Available until 2013.

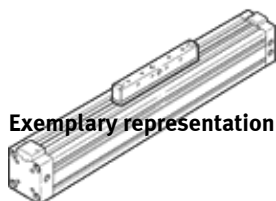

Exemplary representation

 

## Data sheet

Feature	Value
Stroke	10 ... 3,000 mm
Piston diameter	2 1/2"
Cushioning	PPV: Pneumatic cushioning adjustable at both ends YSR: Shock absorber, hard characteristic curve
Guide	Basic guide
Driver principle	positive-locking (slot)
Working pressure	1.5 ... 8 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2
Ambient temperature	-10 ... 60 °C
Cushioning length	30 mm
Pneumatic connection	NPT3/8-18