

Solenoid valve

MN1H-2-1 1/2-MS-NPT

 

Part number: 161735

Classic - do not use for new projects

With manual override, without solenoid coil or socket. Solenoid coil and socket should be ordered separately.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

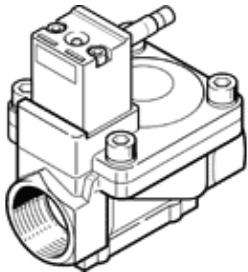

Data sheet

Feature	Value
Design structure	Diaphragm valve
Sealing principle	soft
Assembly position	Any
Mounting type	Line installation
Process valve connection	1 1/2 NPT
Nominal size	40 mm
Valve function	2/2 closed, monostable
Manual override	with accessories, detenting Pushing
Flow direction	non reversible
Medium	Filtered compressed air, degree of filtration 200 µm
Exhaust-air function	not throttleable
Type of reset	Air spring
Type of piloting	Piloted
Medium pressure	0.5 ... 10 bar
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
PWIS conformity	VDMA24364-B1/B2-L
Material screws	High alloy steel, non-corrosive
Material number, screw	1.4301
Product weight	2,600 g
Protection class	IP65