 



Micro filter LFMA-1-H-A

Part number: 162817

FESTO

With 0.01µm filter cartridge, metal bowl guard.
Discontinued, available through 2008

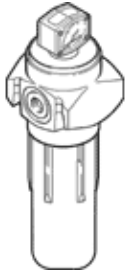

Data sheet

Feature	Value
Assembly position	Vertical +/- 5°
Grade of filtration	0.01 µm
Filter efficiency	99.9999 %
Condensate drain	fully automatic
Design structure	Fiber filter
Differential pressure display	Pressure gauge
Inlet pressure 1	0 ... 16 bar
Standard nominal flow rate	3,400 l/min
Operating medium	Compressed air
Medium temperature	1.5 ... 60 °C
Residual oil content	0.01 mg/m ³
Ambient temperature	-10 ... 60 °C
Product weight	3,200 g
Mounting type	with accessories
Pneumatic connection, port 1	G1
Pneumatic connection, port 2	G1
Materials note	Free of copper and PTFE
Materials information for filter	Boron silicate fiber
Materials information, housing	Zinc die-casting