

 

# Fine filter combination LFMBA-3/4-H-A

Part number: 162822

FESTO

Micro filter 1 µm for prefiltration and micro filter 0.01 µm, with metal bowl guard.

Discontinued, available through 2008

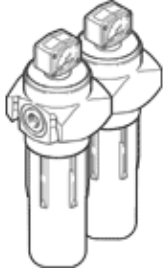

## Data sheet

Feature	Value
Assembly position	Vertical +/- 5°
Grade of filtration	0.01 µm
Filter efficiency	99.9999 %
Condensate drain	fully automatic
Design structure	Fiber filter
Differential pressure display	Pressure gauge
Inlet pressure 1	0 ... 16 bar
Standard nominal flow rate	1,400 l/min
Operating medium	Filtered, unlubricated compressed air, 5 µm filtration Filtered, lubricated compressed air, 5 µm filtration
Medium temperature	1.5 ... 60 °C
Residual oil content	0.01 mg/m <sup>3</sup>
Ambient temperature	-10 ... 60 °C
Product weight	5,740 g
Mounting type	with accessories
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G3/4
Materials information for filter	Boron silicate fiber
Materials information, housing	PA-reinforced
Materials information for bowl	Zinc die-casting