


Module connector PAML-MK-186-HP3

Part number: 1629377

FESTO

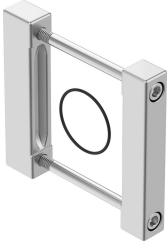

Data sheet

Feature	Value
Size	186
Nominal width DN	54
Series	L
Operating pressure	0 MPa...5 MPa 0 bar...50 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-10 °C...60 °C
For use in the food industry	See supplementary material information
Temperature of medium	5 °C...60 °C
Ambient temperature	5 °C...60 °C
Product weight	1300 g
Note on materials	RoHS-compliant
Seals material	NBR
Module connector material	Wrought aluminum alloy
Material of screws	Stainless steel