


Connecting cable KVIA-MPPE-10

Part number: 163883

FESTO

for proportional valves

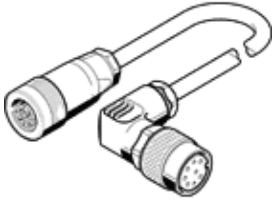

Data sheet

Feature	Value
Mounting type	With sleeve nut
Assembly position	Any
Product weight	828 g
Electrical connection	Plug straight / socket angled
Operating voltage range AC	≤ 250 V
Permissible current load	1 A
Cable length	10 m
Cable diameter	8 mm
Cable structure	6x0,25
Protection class	IP65
Ambient temperature	-30 ... 80 °C
Material cable sheath	PVC
Material housing	PBT
Material electrical contact	Bronze Silver and gold plated