


# Connecting cable KRP-1-24-2,5

Part number: 165612  
Product to be discontinued

FESTO

Connector socket for relay plate for valve terminal CPV with cable.  
Type to be discontinued. Available until 2024. See Support Portal for alternative products.

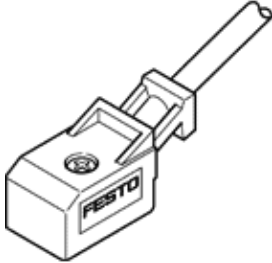

## Data sheet

Feature	Value
Mounting type	with through hole
Assembly position	Any
Product weight	49 g
Electrical connection	2-pin Plug socket angled
Operating voltage range DC	$\leq 26$ V
Operating voltage range AC	$\leq 20$ V
Permissible current load	1 A
Cable length	2.5 m
Cable diameter	3.5 mm
Cable structure	2x0,25
Protection class	IP65
Ambient temperature	-10 ... 50 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Material cable sheath	PVC
Material housing	PUR
Material electrical contact	Bronze