

 

Intermediate pressure regulator plate LR-ZP-A/B-D-1-CT

Part number: 165853

FESTO

For ISO valves.

Run-out type. Available until 2010.

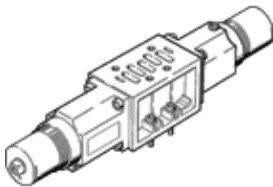

Data sheet

| Feature | Value |
|---------------------------------|----------------------------|
| Based on the standard | ISO 5599-1 |
| Integrated function | Pressure regulator |
| Design structure | Piston |
| Pressure control range | 0 ... 12 bar |
| Inlet pressure 1 | ≤ 14 bar |
| Product weight | 840 g |
| Materials note | Free of copper and PTFE |
| Materials information for seals | NBR |
| Materials information, housing | Aluminum die cast Steel |