


Expansion module CMGA-E1-PB

Part number: 1680827

FESTO

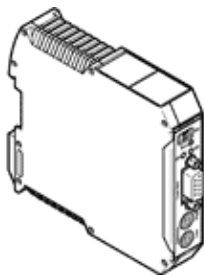

Data sheet

Feature	Value
Logic input working range	20.4 ... 28.8 V
Nominal DC voltage, logic power supply	24 V
Permissible range, logic voltage	-15% - 20%
Nominal operating voltage DC	24 V
Nominal current, logic supply	≤ 2 A
Power consumption 24 V	≤ 2.4 W
Encoder interface input, function	No
Display	LED
Control elements	DIP switches Rotary coding switch
Protection class	IP20
Ambient temperature	0 ... 50 °C
Storage temperature	-10 ... 70 °C
Product weight	110 g
Dimensions W x L x H	22,5 mm x 115 mm x 100 mm
Mounting type	with top-hat rail
Assembly position	Vertical Free convection
Bus connection	9-pin Sub-D
Fieldbus coupling	Profibus DP
Max. fieldbus transmission speed	12 Mbit/s
Materials note	Contains PWIS substances Conforms to RoHS