

Heavy-duty guide HD-12- -

Part number: 170024


FESTO

Configurable

To configure first add product to the shopping basket.

Depending on configuration, the technical data given on the data sheet and the relevant accessories might not match exactly for this product.

Type to be discontinued. Available until 2009.

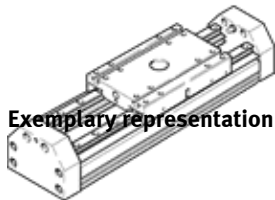

Exemplary representation

Data sheet

~ConfIndependentDatasheet

Feature	Value
Size	12
Stroke	10 ... 1,550 mm
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide axis without actuator
Max. speed	3 m/s
Corrosion resistance classification CRC	0
Ambient temperature	-10 ... 60 °C
Max. force Fy	1,120 N
Max. force Fz	1,120 N
Max. torque Mx	33.6 Nm
Max. torque My	50.4 Nm
Max. torque Mz	49 Nm
Moving mass	330 g
Moving mass with 0 mm stroke	330 g
Additional weight per 10 mm stroke	46 g
Basic weight for 0 mm stroke	1,370 g
Materials information for guide component	Steel
Materials information, housing	Wrought Aluminum alloy Anodized