


# Blanking plug QSP17-PTB

Part number: 172996

FESTO

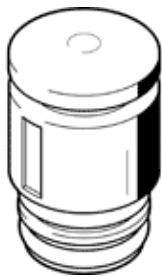

## Data sheet

Feature	Value
Size	Standard
Assembly position	Any
Design	Straight design
Container size	1
Operating pressure for entire temperature range	0.095 ... 1 MPa
Operating pressure complete temperature range	0.95 ... 10 bar
Operating pressure for entire temperature range	13.775 ... 145 psi
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Note on operating and pilot medium	Lubricated operation possible
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	4.7 g
Mounting type	Mounting pin
Pneumatic connection, port 1	Cartridge 17 mm
Materials note	Conforms to RoHS
Material housing	PA
Material of tubing seal	NBR