


# Connecting cable KMP1-02-VI-6-5

Part number: 175585  
Product to be discontinued

FESTO

For valve manifold VIMP-02, fully assembled for four to six valve positions, 5 m long.

Type to be discontinued. Available until 2017. See Support Portal for alternative products.

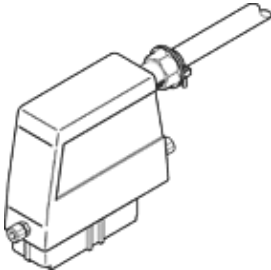

## Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	$\leq 300$ V
Operating voltage range DC	$\leq 250$ V
Permissible current load	4 A
Protection class	IP65
Ambient temperature with flexible cable installation	5 ... 70 °C
Ambient temperature	-30 ... 70 °C
Product weight	1,200 g
Electrical connection	25-pin Plug socket
Cable structure	13 x 0,75 mm <sup>2</sup>
Cable diameter	10 mm
Cable length	5 m
Mounting type	With clamp strap
Materials information, housing	Die-cast light alloy
Materials information, cable sheaths	PE
Material information for crimp connectors	Copper alloy Silver plated