 



Silencer UC-QS-8H

Part number: 175611

FESTO

For CPE valves or CPV valve manifolds, with connector socket for QS fittings.

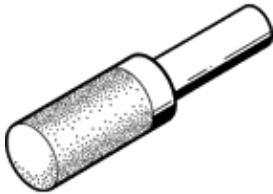

Data sheet

Feature	Value
Assembly position	Any
Container size	1
Operating pressure MPa	0 ... 1 MPa
Working pressure	0 ... 10 bar
Flow rate to atmosphere	1,500 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Note on operating and pilot medium	Lubricated operation possible
PWIS conformity	VDMA24364-B1/B2-L
Sound pressure level	60 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	2.3 g
Pneumatic connection	QS-8
Material of silencer insert	PE
Material of threaded plug	PE
Materials note	Conforms to RoHS