

Non-return valve HAM-1/16-QS-1/8-U

Part number: 190939


FESTO

Flow rate from the male thread to the QS plug connector.

This product is only available if ordered from the Festo Corporation, USA.

This type is suitable for vacuum.

Type to be discontinued. Available until 2011.

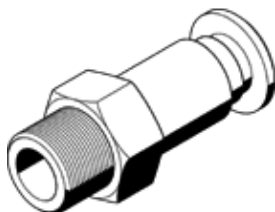

Data sheet

Feature	Value
Valve function	Non-return function
Pneumatic connection, port 1	NPT1/16-27
Pneumatic connection, port 2	QS-1/8
Mounting type	Threaded
Working pressure	-1 ... 10 bar
Ambient temperature	0 ... 60 °C
Materials information, housing	Brass
Operating medium	Compressed air, filtered, unlubricated Filtered, lubricated air
Product weight	13 g