

# Service unit FRC-1/2-D-7-DI-MAXI

Part number: 192408

Classic - do not use for new projects

 

Filter regulator/lubricator combination, maximum output pressure 7 bar, 40 µm filter, with metal bowl guard.

With manual condensate drain. With pressure gauge. With directly-controlled pressure regulator.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

Type to be discontinued. Available until 2022. See Support Portal for alternative products.

FESTO

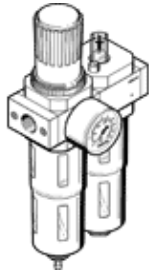

## Data sheet

| Feature                      | Value   |
|------------------------------|---|
| Size                         | Maxi  |
| Series                       | D   |
| Actuator lock                | Rotary knob with lock   |
| Assembly position            | Vertical +/- 5°   |
| Condensate drain             | manual rotary   |
| Design structure             | Filter regulator with pressure gauge<br>proportional standard mist lubricator |
| Max. condensate volume       | 43 cm <sup>3</sup>  |
| Grade of filtration          | 40 µm   |
| Bowl guard                   | Metal bowl guard  |
| Pressure gauge               | with pressure gauge   |
| Working pressure             | 1 ... 16 bar  |
| Pressure regulation range    | 0.5 ... 7 bar   |
| Max. pressure hysteresis     | 0.4 bar   |
| Standard nominal flow rate   | 4,500 l/min   |
| Maritime classification      | see certificate   |
| Operating medium             | Compressed air in accordance with ISO8573-1:2010 [-:--]                       |
| Medium temperature           | -10 ... 60 °C   |
| Ambient temperature          | -10 ... 60 °C   |
| Product weight               | 2,600 g   |
| Mounting type                | Line installation   |
| Pneumatic connection, port 1 | G1/2  |
| Pneumatic connection, port 2 | G1/2  |
| Material housing             | Zinc die-casting  |
| Material bowl                | PC  |